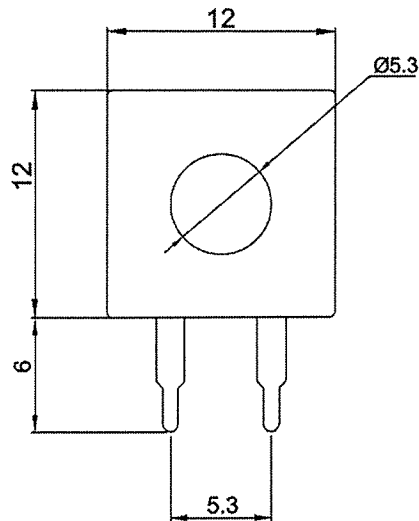


SPECIFICATIONS:

Rating: DC30V 1A ;
 Contact resistance: 100m Ω (Max.) ;
 Insulation resistance: DC500V 100M Ω (Min.) ;
 Withstand voltage: AC 1000V for 1 minute ;
 Operating force: 500 $\pm$ 200gf ;
 Life cycle: 20,000 cycles ;
 Total Travel: 1.5 $\pm$ 0.3mm .




MATERIAL:

Frame: PBT,UL rated:94V-2 Min. ;
 Cap: POM;
 Terminal:Brass,Silver or Tin plated .

Function:

ON(1-6)-OFF

Cap Color: Black

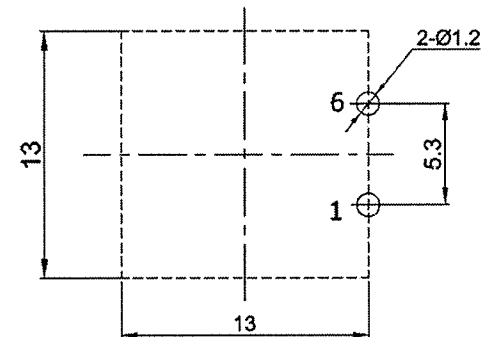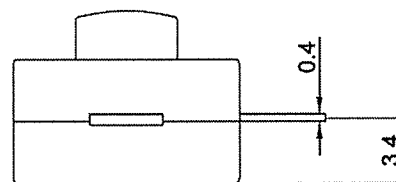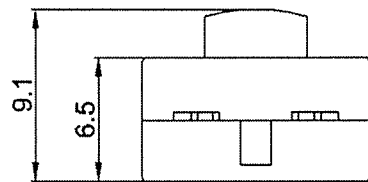

P.C.B.LAYOUT(BottomView)

RoHS Compliant

CW INDUSTRIES
 Southampton, Pa. 18966
 Tel 215.355.7080/www.cwind.com

1 Push Button Switch was Torch Switch in title. 6-05-12.				
Date Drawn: 3-22-12	Rev. 1	Unit: mm	Checked By: <i>G. Guld</i>	
Title: PUSH BUTTON SWITCH		CW P/N: GPTS203212B		