


156-00537

Cable Tie and Edge Clip, 50lb, 8.0" Long, EC19, Panel Thickness .12"-.24", PA66HS, Black, 500/bag

Article Number: 156-00537

Part Number: 156-00537

Type: T50REC19

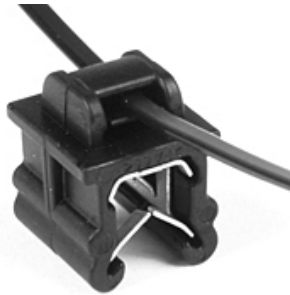

[Find a Distributor](#)

[Order Samples](#)

[Get Technical Drawings](#)

| [Share](#)

Base Data

Part No.	156-00537
Type	T50REC19
Color	Black (BK)
Features	• Edge Clip applies easily to plastic and metal sheets without the need for a mounting hole. • Edge Clip provides low insertion force and high extraction force ideal for assembly environments. • Two piece assembly allows the mount to slide along the strap ensuring proper orientation.
Application Method	Cable tie and edge clip assemblies are primarily applied around a bundle by hand and tensioned using one of HellermannTyton's manual or pneumatic hand tools. The bundle is then secured to the mounting surface by inserting the clip onto the appropriate edge.
Identification Plate Position	none
Typical Application	This cable tie and edge clip assembly is ideal for use where holes are not acceptable or where adhesives will fail due to temperature problems. Edge clips are widely used for fixing and bundling cables and wires within automotive, trucking, heavy equipment, solar panel, wind power, and white goods equipment manufacturing.
Variant	Inside Serrated

Product Dimensions

Min. Tensile Strength	50.0lbs / 225N
Length (L)	8.0" / 200.0mm
Length (L2)	0.58" / 14.8mm
Width (W) (imperial)	0.18"
Width (W)	4.6mm
Width (W2)	0.58" / 14.8mm
Height (H)	0.05" / 1.2mm
Height (H2)	0.7" / 17.8mm
Min. Ø Bundle	0.06" / 1.0mm
Max. Ø Bundle	2.0" / 45.0mm
Max. Panel Thickness	0.24" / 6.00mm

Min. Panel Thickness	0.12" / 3.00mm
----------------------	----------------

 Material and Specifications

Material	Polyamide 6.6 heat stabilized (PA66HS) / Polyamide 6.6 high impact modified, heat stabilized, UV resistant (PA66HIRHS)
Material Specification	RoHS

 Logistic and Packaging

Packaging Type	bag
Pkg. Qty.	500
Carton Qty.	3000
EAN code	4031026324784
UPC	089306310068

[Find a Distributor](#)

[Get Product Samples](#)

[Get Technical Drawings](#)