

CTAP110C2

Cable Tie Anchor Plates, 0.2x.75" Hole Dia., 0.2" Max Tie Width, PA66, White, 100/pkg

Article Number: 151-30100

Part Number: CTAP110C2

Type: CTAP1



[Find a Distributor](#)

[Order Samples](#)


[Get Technical Drawings](#)

[Share](#)

Base Data

Part No.	CTAP110C2
Type	CTAP1
Color	White (WH)
Features	- Mount provides a "stand-off" for perpendicular bundles. - Secures with a single screw providing quick installation.
Application Method	Once aligned, plate is fastened securely by tightening the applied #10 screw.
Typical Application	Plates are used perpendicularly to the wire bundle.

Product Dimensions

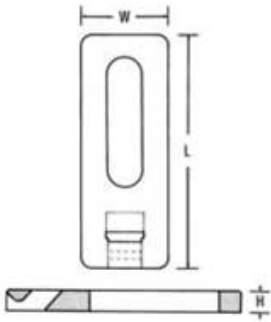

Length (L)	1.34" / 34.0mm
Width (W) (imperial)	0.5"
Width (W)	12.7mm
Max. Cable Tie Width	0.2" / 5.0mm
Height (H)	0.15" / 3.8mm
Mounting Hole Ø	0.2 x 0.75" / 5.0 x 19.0mm

Material and Specifications

Material	Polyamide 6.6 (PA66)
CSA Certified	No
Flammability	UL94 V2

Material Specification	RoHS
Operating Temperature	-40 °F to +185 °F (-40 °C to +85 °C)
ROHS Conformity	 RoHS
Specification	UL
UL Listed (US and Canada)	No
UL Recognized (US and Canada)	Yes

 Logistic and Packaging

Packaging Type	bag
Pkg. Qty.	100
Carton Qty.	5000
EAN code	4031026312514
UPC	089306011804

[Find a Distributor](#)

[Get Product Samples](#)

[Get Technical Drawings](#)

[Home](#) | [About HellermannTyton](#) | [Products](#) | [Careers](#) | [Contact](#) | [Terms](#)

© HellermannTyton North America 2011 | [TS16949](#), [ISO 9001](#) and [ISO 14001 Certified](#)
7930 N. Faulkner Rd. Milwaukee, WI 53224-9517 | Fax: 800-848-9866 | Phone: 800-537-1512