

MMB.50M4

Masonry Mount, 1.24" Length, .25" Hole Dia., .18" Max. Cable Tie Width, PA46, Black, 1000/pkg

Article Number: 151-30001

Part Number: MMB.50M4

Type: MMB.5



→ Find a Distributor

→ Order Samples

→ Get Technical Drawings


Share

- ▶ Cable Ties
- ▶ Cable Ties with Fasteners
- ▶ Cable Tie Tools
- ▶ Clamps and Clips
- ▶ Heatshrink Moulded Shapes
- ▼ Mounts
 - Adhesive Fastened Bases
 - Screw Fastened Bases
 - Mounting Plates
 - Screw Mount
 - Push Mount
 - Masonry Mounts**
 - Bundle Separator-Spacer
 - Grip Tie Mounts
 - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
 - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

Base Data

Part No.	MMB.50M4
Type	MMB.5
Color	Black (BK)
Features	<ul style="list-style-type: none"> Masonry Mounts provides a permanent solution when fastening wire and cables to masonry surfaces. The mounts have easy installation into predrilled holes allowing for faster use.
Application Method	HellermannTyton's masonry mounts simply tap into predrilled holes.
Typical Application	Can be used for indoor and outdoor applications.

Product Dimensions

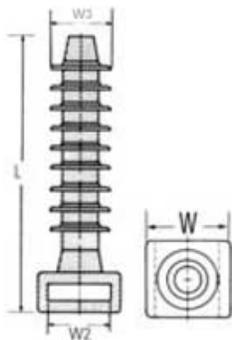

Length (L)	1.24" / 31.5mm
Width (W) (imperial)	0.375"
Width (W)	9.5mm
Max. Cable Tie Width	0.18" / 4.6mm
Width (W2)	.220" / 5.6mm
Width (W3)	.308" / 7.8mm
Height (H)	9.4mm
Mounting Hole Ø	0.25" / 6.35mm
Width of Fixing WF (metric)	7.7mm

Material and Specifications

Material	Polyamide 4.6 (PA46)
Flammability	UL94 V2
Material Specification	RoHS
Operating Temperature	-40 °F to +275 °F (-40 °C to +135 °C)

Logistic and Packaging

Packaging Type	bag
Pkg. Qty.	1000
Carton Qty.	9000
UPC	089306212584

[Find a Distributor](#)[Get Product Samples](#)[Get Technical Drawings](#)

[Home](#) | [About HellermannTyton](#) | [Products](#) | [Careers](#) | [Contact](#) | [Terms](#)

© HellermannTyton North America 2011 | [TS16949](#), [ISO 9001](#) and [ISO 14001 Certified](#)

7930 N. Faulkner Rd. Milwaukee, WI 53224-9517 | Fax: 800-848-9866 | Phone: 800-537-1512