

MMB10C2

Masonry Mount, 1.712" Length, .312" Hole Dia., .18" Max. Cable Tie Width, PA46, Black, 100/pkg

Article Number: 151-00326

Part Number: MMB10C2

Type: MMB1



→ Find a Distributor

→ Order Samples

→ Get Technical Drawings

| Share

- ▶ Cable Ties
- ▶ Cable Ties with Fasteners
- ▶ Cable Tie Tools
- ▶ Clamps and Clips
- ▶ Heatshrink Moulded Shapes
- ▼ Mounts
 - Adhesive Fastened Bases
 - Screw Fastened Bases
 - Mounting Plates
 - Screw Mount
 - Push Mount
- ▶ **Masonry Mounts**
 - Bundle Separator-Spacer
 - Grip Tie Mounts
 - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
 - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

Base Data

Part No. MMB10C2

Type MMB1

Color Black (BK)


Features

- Masonry Mounts provides a permanent solution when fastening wire and cables to masonry surfaces.
- The mounts have easy installation into predrilled holes allowing for faster use.

Application Method HellermannTyton's masonry mounts simply tap into predrilled holes.

Typical Application Can be used for indoor and outdoor applications.

Product Dimensions

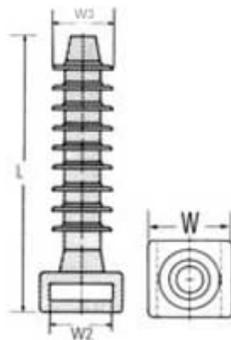

Length (L) 1.712" / 43.5mm

Width (W) (imperial) 0.508"

Width (W) 12.9mm

Max. Cable Tie Width 0.18" / 4.6mm

Width (W2) .374" / 9.5mm

Width (W3) .362" / 9.2mm

Height (H) 12.7mm

Mounting Hole Ø 0.312" / 8.0mm

Width of Fixing WF (metric) 7.8mm

➔ Material and Specifications

| | |
|-------------------------------|---------------------------------------|
| Material | Polyamide 4.6 (PA46) |
| Flammability | UL94 V2 |
| Material Specification | RoHS |
| Operating Temperature | -40 °F to +275 °F (-40 °C to +135 °C) |

➔ Logistic and Packaging

| | |
|-----------------------|--------------|
| Packaging Type | bag |
| Pkg. Qty. | 100 |
| Carton Qty. | 5000 |
| UPC | 089306027812 |

[Find a Distributor](#)[Get Product Samples](#)[Get Technical Drawings](#)[Home](#) | [About HellermannTyton](#) | [Products](#) | [Careers](#) | [Contact](#) | [Terms](#)© HellermannTyton North America 2011 | [TS16949](#), [ISO 9001](#) and [ISO 14001 Certified](#)

7930 N. Faulkner Rd. Milwaukee, WI 53224-9517 | Fax: 800-848-9866 | Phone: 800-537-1512