

- ▶ Cable Ties
- ▶ Cable Ties with Fasteners
- ▶ Cable Tie Tools
- ▶ Clamps and Clips
- Heatshrink Moulded Shapes
- ▼ Mounts
  - Adhesive Fastened Bases
  - Screw Fastened Bases
  - Mounting Plates
  - Screw Mount
  - Push Mount
  - Masonry Mounts
  - Bundle Separator-Spacer
  - Grip Tie Mounts
  - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
  - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

MP2M5.NN3P

Cable Tie Mounting Plates .50"X3.00" - PA66, Natural, T18-T50 Cable Ties, #10 (M5) Screw, 100/pk

Article Number: 154-00300

Part Number: MP2M5.NN3P

Type: MP2M5



→Find a Distributor

→Order Samples


→Get Technical Drawings

| Share

→ Base Data

|                     |                                                                                                                                           |
|---------------------|-------------------------------------------------------------------------------------------------------------------------------------------|
| Part No.            | MP2M5.NN3P                                                                                                                                |
| Type                | MP2M5                                                                                                                                     |
| Color               | Natural (NA)                                                                                                                              |
| Features            | The cables are attached to the mounting plate by using a T18 through T50 series cable tie through any combination of the available slots. |
| Application Method  | These mounting plates are secured with two #10 (M5) screws.                                                                               |
| No. of bundles      | 2                                                                                                                                         |
| Typical Application | Allows multiple cables to be run in parallel.                                                                                             |

→ Product Dimensions

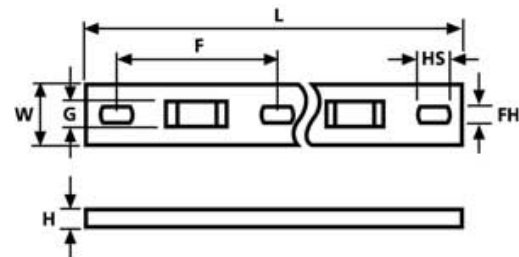

|                       |                |
|-----------------------|----------------|
| Length (L)            | 3.00" / 76.2mm |
| Width (W) (imperial)  | .50"           |
| Width (W)             | 12.7mm         |
| Max. Cable Tie Width  | 5.2mm          |
| Height (H)            | .125" / 3.2mm  |
| Mounting Hole Ø       | .20" / 5.1mm   |
| Hole Size             | 7.6mm          |
| Mounting Hole Centers | 31.8mm         |

→ Material and Specifications

|              |                      |
|--------------|----------------------|
| Material     | Polyamide 6.6 (PA66) |
| Flammability | UL94 V2              |