

- ▶ Cable Ties
 - ▶ Cable Ties with Fasteners
 - ▶ Cable Tie Tools
 - ▶ Clamps and Clips
 - Heatshrink Moulded Shapes
- ▼ Mounts
 - Adhesive Fastened Bases
 - Screw Fastened Bases
 - Mounting Plates
 - Screw Mount
 - Push Mount
 - Masonry Mounts
 - Bundle Separator-Spacer
 - Grip Tie Mounts
 - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
 - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

MP3M3.NN3P

Cable Tie Mounting Plates .50"X4.25" - PA66, Natural, T18-T50 Cable Ties, #6 (M3) Screw, 100/pk

Article Number: 151-24319

Part Number: MP3M3.NN3P

Type: MP3M3




- ➔ [Find a Distributor](#)
- ➔ [Order Samples](#)
- ➔ [Get Technical Drawings](#)



➔ Base Data

Part No.	MP3M3.NN3P
Type	MP3M3
Color	Natural (NA)
Features	The cables are attached to the mounting plate by using a T18 through T50 series cable tie through any combination of the available slots.
Application Method	These mounting plates are secured with two #6 (M3) screws.
No. of bundles	3
Typical Application	Allows multiple cables to be run in parallel.

➔ Product Dimensions

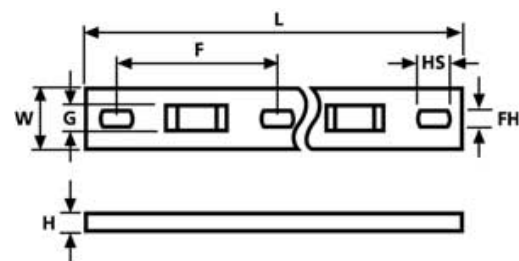

Length (L)	4.25" / 108.0mm
Width (W) (imperial)	.50"
Width (W)	12.7mm
Max. Cable Tie Width	5.2mm
Height (H)	.125" / 3.2mm
Mounting Hole Ø	.15" / 3.7mm
Mounting Hole Centers	1.25"
Hole Size	6.4mm
Mounting Hole Centers	31.8mm

➔ Material and Specifications

Material	Polyamide 6.6 (PA66)
----------	----------------------