

- ▶ Cable Ties
- ▶ Cable Ties with Fasteners
- ▶ Cable Tie Tools
- ▶ Clamps and Clips
- ▶ Heatshrink Moulded Shapes
- ▼ Mounts
 - Adhesive Fastened Bases
 - Screw Fastened Bases
 - Mounting Plates**
 - Screw Mount
 - Push Mount
 - Masonry Mounts
 - Bundle Separator-Spacer
 - Grip Tie Mounts
 - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
 - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

MP3M5.NN3P

Cable Tie Mounting Plates .50"X4.25" - PA66, Natural, T18-T50 Cable Ties, #10 (M5) Screw, 100/pk

Article Number: 154-00500

Part Number: MP3M5.NN3P

Type: MP3M5



→ [Find a Distributor](#)

→ [Order Samples](#)


→ [Get Technical Drawings](#)

| Share

→ **Base Data**

Part No.	MP3M5.NN3P
Type	MP3M5
Color	Natural (NA)
Features	The cables are attached to the mounting plate by using a T18 through T50 series cable tie through any combination of the available slots.
Application Method	These mounting plates are secured with two #10 (M5) screws.
No. of bundles	3
Typical Application	Allows multiple cables to be run in parallel.

→ **Product Dimensions**

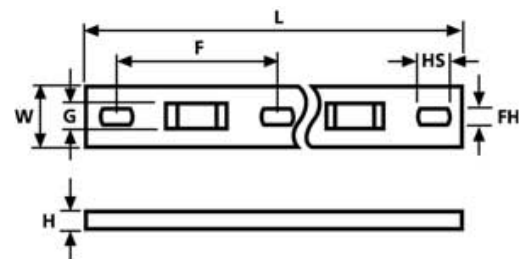

Length (L)	4.25" / 108.0mm
Width (W) (imperial)	.50"
Width (W)	12.7mm
Max. Cable Tie Width	5.2mm
Height (H)	.125" / 3.2mm
Mounting Hole Ø	.20" / 5.1mm
Mounting Hole Centers	1.25"
Hole Size	7.6mm
Mounting Hole Centers	31.8mm

→ **Material and Specifications**

Material	Polyamide 6.6 (PA66)
----------	----------------------