

- ▶ Cable Ties
- ▶ Cable Ties with Fasteners
- ▶ Cable Tie Tools
- ▶ Clamps and Clips
- ▶ Heatshrink Moulded Shapes
- ▼ Mounts
 - Adhesive Fastened Bases
 - Screw Fastened Bases
 - Mounting Plates**
 - Screw Mount
 - Push Mount
 - Masonry Mounts
 - Bundle Separator-Spacer
 - Grip Tie Mounts
 - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
 - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

MP5M3.NN3P

Cable Tie Mounting Plates .50"X6.75" - PA66, Natural, T18-T50 Cable Ties, #6 (M3) Screw, 100/pk

Article Number: 151-24519

Part Number: MP5M3.NN3P

Type: MP5M3



➔Find a Distributor

➔Order Samples


➔Get Technical Drawings

| Share

➔Base Data

Part No.	MP5M3.NN3P
Type	MP5M3
Color	Natural (NA)
Features	The cables are attached to the mounting plate by using a T18 through T50 series cable tie through any combination of the available slots.
Application Method	These mounting plates are secured with two #6 (M3) screws.
No. of bundles	5
Typical Application	Allows multiple cables to be run in parallel.

➔Product Dimensions

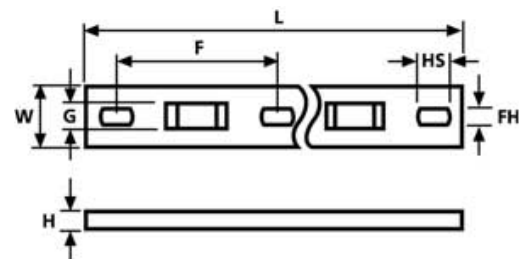

Length (L)	6.75" / 171.6mm
Width (W) (imperial)	.50"
Width (W)	12.7mm
Max. Cable Tie Width	5.2mm
Height (H)	.125" / 3.2mm
Mounting Hole Ø	.15" / 3.7mm
Mounting Hole Centers	1.25"
Hole Size	6.4mm
Mounting Hole Centers	31.8mm

➔Material and Specifications

Material	Polyamide 6.6 (PA66)
----------	----------------------