

- ▶ Cable Ties
- ▶ Cable Ties with Fasteners
- ▶ Cable Tie Tools
- ▶ Clamps and Clips
- Heatshrink Moulded Shapes
- ▼ Mounts
  - Adhesive Fastened Bases
  - Screw Fastened Bases
  - Mounting Plates**
  - Screw Mount
  - Push Mount
  - Masonry Mounts
  - Bundle Separator-Spacer
  - Grip Tie Mounts
  - Q Mounts
- ▶ Heavy Duty Mounts
- ▶ Wire Connectors
- ▶ Wiring Duct
- ▶ Wiring Protection
- ▶ Labels, Printers and Software
  - Pre-Terminated Networking
- ▶ Copper Network Solutions
- ▶ Fiber Network Solutions
- ▶ Jacks and Wall Plates
- ▶ Racks - Cable Management
- ▶ Surface Raceway Systems

MP5M5.NN3P

Cable Tie Mounting Plates .50"X6.75" - PA66, Natural, T18-T50 Cable Ties, #10 (M5) Screw, 100/pk

Article Number: 154-00900

Part Number: MP5M5.NN3P

Type: MP5M5

➔Find a Distributor

➔Order Samples


➔Get Technical Drawings

 Share

➔Base Data

|                     |                                                                                                                                           |
|---------------------|-------------------------------------------------------------------------------------------------------------------------------------------|
| Part No.            | MP5M5.NN3P                                                                                                                                |
| Type                | MP5M5                                                                                                                                     |
| Color               | Natural (NA)                                                                                                                              |
| Features            | The cables are attached to the mounting plate by using a T18 through T50 series cable tie through any combination of the available slots. |
| Application Method  | These mounting plates are secured with two #10 (M5) screws.                                                                               |
| No. of bundles      | 5                                                                                                                                         |
| Typical Application | Allows multiple cables to be run in parallel.                                                                                             |

➔Product Dimensions

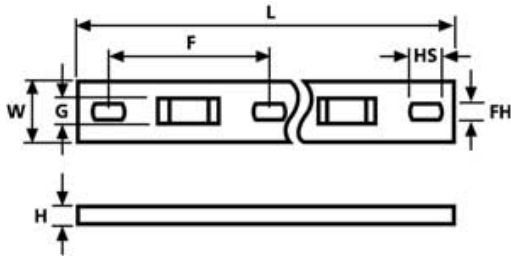

|                       |                 |
|-----------------------|-----------------|
| Length (L)            | 6.75" / 171.6mm |
| Width (W) (imperial)  | .50"            |
| Width (W)             | 12.7mm          |
| Max. Cable Tie Width  | 5.2mm           |
| Height (H)            | .125" / 3.2mm   |
| Mounting Hole Ø       | .20" / 5.1mm    |
| Mounting Hole Centers | 1.25"           |
| Hole Size             | 7.6mm           |
| Mounting Hole Centers | 31.8mm          |

➔Material and Specifications

|                        |                                                                                     |
|------------------------|-------------------------------------------------------------------------------------|
| Material               | Polyamide 6.6 (PA66)                                                                |
| Flammability           | UL94 V2                                                                             |
| Material Specification | RoHS                                                                                |
| Operating Temperature  | -40 °F to +185 °F (-40 °C to +85 °C)                                                |
| ROHS Conformity        |  |