

Part Search



Part Number . . .

FFY.00.250.NTAC52



Size/Series 00 / 00

[Demande d'offres](#)

MECHANICAL DETAILS

Shell Style/Model FFY*: Straight plug with cable collet
Keying Circular (can rotate)
Housing Material Brass (nickel plated) shell, collet nut, latch sleeve and mid pieces
Cable Fixing C52: 4.6 - 5 mm
Variant :

	A	L	M
mm.	8.9	33	25
in.	0.35	1.30	0.98

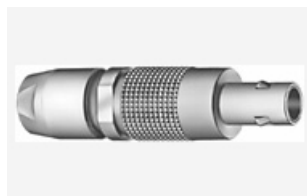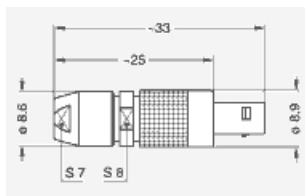

MECHANICAL DETAILS

Insert Configuration 0.25 : 1 Coax (50 Ohm)
Insulator T: PTFE
Specifications
Contact Type: Coaxial 50 Ohm (Solder)
Max. Matings: 5000
Contact Dia.: 0.7 mm (0.028in)
Bucket Dia.: 0.6 mm (0.024in)
R (max): 6.1 mOhm
Vtest: 2100 V (AC), 3000 V (DC)
Rated Current: 4 A (AC/DC)
Impedance: 50 Ohm
VSWR: 1.09 + 0.11 * f/GHz
Cable type: RG 58 C/U

MECHANICAL DETAILS

Endurance (Shell) 3839 mating cycles
F ret (min): 100 N
IP Rating 50
Catalog



[Copyright](#) [Privacy policy](#) [Product safety](#)