

KRM31FR61E106KH01#

" # " indicates a package specification code.

Recommended

Reflow OK

Complies with RoHS


Anti-noise

Deflecting crack

Soldering crack

< List of part numbers with package codes >
KRM31FR61E106KH01L , KRM31FR61E106KH01K

Shape

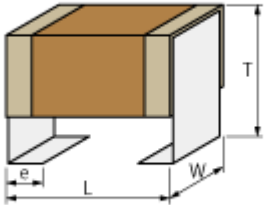

L size	3.5 ± 0.3mm
W size	1.7 ± 0.2mm
T size	1.9 ± 0.1mm
Metal terminal width e	0.8 ± 0.2mm
Size code in inch(mm)	1206 (3216)

References

Packaging	Specifications	Minimum quantity
L	φ 180mm Embossed taping	1500
K	φ 330mm Embossed taping	5000

Mass (typ.)	
1 piece	40mg

Specifications

Capacitance	10μF ± 10%
Rated voltage	25Vdc
Temperature characteristics (complied standard)	X5R(EIA)
Capacitance change rate	± 15%
Temperature range of temperature characteristics	-55 to 85
Operating temperature range	-55 to 85

 Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it ' s specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications.
- Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.