


3M™ Dissipative Rubber Mats and Rolls 8800 Series

Premium Performance

3M™ Dissipative Rubber Mats and Rolls 8800 Series are comprised of a new improved formula, consisting of a top layer of static dissipative neoprene rubber laminated to a bottom layer of conductive neoprene rubber. Both layers are made from vulcanized synthetic rubber, which offers excellent resistance to oil, grease and most common solvents. They offer excellent resistance to heat and hot solder as compared to vinyl or olefinic materials. Non-standard sizes are available on a custom order basis. Compatible with 3M constant monitors.

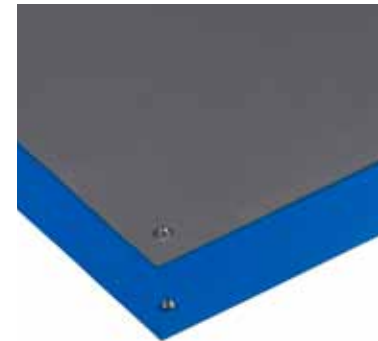

3M™ Dissipative Rubber Mats and Rolls 8800 Series

Product Bulletin

Properties	Typical Value
Material	Top and bottom layers - Neoprene
Thickness	0.065 in. (1.7 mm)
Hardness	60 Shore A
*Resistance	
Surface to Ground (RTG)	3 x 10 ⁶ ohms
Surface to Surface (STG)	5 x 10 ⁷ ohms
Tolerances	Width +/- .250" Length +/- .250"

*Tested per ESD Association Standard S4.1 at 72°F, 50% RH using 3M Test Kit 701 for Static Control Surfaces (Megohmmeter). Small variations in color and appearance of mats may vary by lot.

Product Kits

Product No.	Description	Size (ft.)	(m)
Includes one 15 ft. (4.6 m) 3M™ Ground Cord 3040 and two 3M™ Snap Fasteners 3034, installed			
8870	Floor Mat, Gray	4 x 6	(1.2 x 1.8)
8871	Floor Mat, Blue	4 x 6	(1.2 x 1.8)
Includes two 15 ft. (4.6 m) 3M Ground Cords 3040 and five 3M Snap Fasteners 3034, not installed			
8880	Floor Roll, Gray	4 x 24	(1.2 x 7.3)
8881	Floor Roll, Blue	4 x 24	(1.2 x 7.3)

Non-standard sizes available on custom order basis up to 50 ft. (15.2 m) maximum length.

3M™ Dissipative Rubber Mats and Rolls 8800 Series

Product Kits cont.

Product No.	Description	Size (ft.)	(m)
Includes two 3M™ Snap Fasteners 3034 and one 3M™ Wrist Strap Grounding System 3048			
8810	Table Mat, Gray	2 x 4	(0.6 x 1.2)
8811	Table Mat, Blue	2 x 4	(0.6 x 1.2)
8830	Table Mat, Gray	3 x 4	(0.9 x 1.2)
8831	Table Mat, Blue	3 x 4	(0.9 x 1.2)
88A0	Table Mat, Gray	2 x 3	(0.6 x 0.9)
88A1	Table Mat, Blue	2 x 3	(0.6 x 0.9)
Includes two 15 ft. (4.6 m) 3M™ Ground Cords 3040 and five 3M Snap Fasteners 3034, not installed			
8840	Table Roll, Gray	2 x 24	(0.6 x 7.3)
8841	Table Roll, Blue	2 x 24	(0.6 x 7.3)
8860	Table Roll, Gray	3 x 24	(0.9 x 7.3)
8861	Table Roll, Blue	3 x 24	(0.9 x 7.3)
These mats do not come with additional hardware			
8800	Table Roll, Gray	2 x 40	(0.6 x 12.2)
8801	Table Roll, Blue	2 x 40	(0.6 x 12.2)
8820	Table Roll, Gray	2.5 x 40	(0.8 x 12.2)
8821	Table Roll, Blue	2.5 x 40	(0.8 x 12.2)
8850	Table Roll, Gray	3 x 40	(0.9 x 12.2)
8851	Table Roll, Blue	3 x 40	(0.9 x 12.2)
8890	Floor Roll, Gray	4 x 40	(1.2 x 12.2)
8891	Floor Roll, Blue	4 x 40	(1.2 x 12.2)

Non-standard sizes available on custom order basis up to 50 ft. (15.2 m) maximum length.

Material might have slight color and texture variance between lots

Mat rolls need to be unrolled before being cut. When rolled some shrinkage may occur. Please allow time for mat to relax at room temperature 24-48 hours prior to cutting.

Roll Width Tolerance: +/- .25"

Cut Mats Have a Tolerance of +/- .25" on width and length

3M is a trademark of 3M Company.

Important Notice

All statements, technical information, and recommendations related to 3M's products are based on information believed to be reliable, but the accuracy or completeness is not guaranteed. Before using this product, you must evaluate it and determine if it is suitable for your intended application. You assume all risks and liability associated with such use. Any statements related to the product which are not contained in 3M's current publications, or any contrary statements contained on your purchase order shall have no force or effect unless expressly agreed upon, in writing, by an authorized officer of 3M.

Warranty; Limited Remedy; Limited Liability.

This product will be free from defects in material and manufacture for a period of one year from the time of purchase. **3M MAKES NO OTHER WARRANTIES INCLUDING, BUT NOT LIMITED TO, ANY IMPLIED WARRANTY OF MERCHANTABILITY OR FITNESS FOR A PARTICULAR PURPOSE.** If this product is defective within the warranty period stated above, your exclusive remedy shall be, at 3M's option, to replace or repair the 3M product or refund the purchase price of the 3M product. **Except where prohibited by law, 3M will not be liable for any indirect, special, incidental or consequential loss or damage arising from this 3M product, regardless of the legal theory asserted.**



Electronic Solutions Division Static Control Products

926 JR Industrial Drive
Sanford, NC 27332-9733
Toll-Free: 866-722-3736
International: 919-718-0000
Email: 3mstaticinfo@mmm.com
www.3Mstatic.com

Please recycle. Printed in U.S.A.
© 3M 2012. All rights reserved.
98-0799-1078-6