



CA0221S0502

COMPACT ALPHA



PRODUCT FEATURES

Power usage	12 W
Power supply	24 Vdc
Light source	LED
Electrical connection	Cable 3m (10ft)
Color temperature	5000K, CRI 80
Luminous flux	1200 lm
Efficiency	100 lm/W
Light beam angle	90°
Housing	Anodized aluminum
Front protection	Tempered glass
Protection index	IP67 (compatible with NEMA TYPE 12)
Impact resistance	IK06
Operating temperature	-20°C to + 45°C (-04°F to +113°F)
Weight	0,75 kg (1,65 lb)
Agency approvals	cURus in compliance with UL2108, CSA C22.2, CE, RoHS
Mounting	CAFX02 Stainless-Steel Brackets

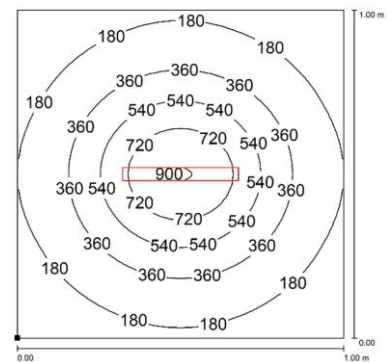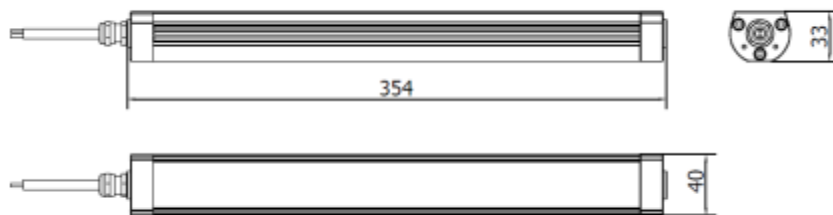

NOTE: Installation Height: 1m