


Part Number: 339-3383

Type	Size	Rating	Description
Incandescent	T16	24V 200mA	BA15d Indicator Lamp

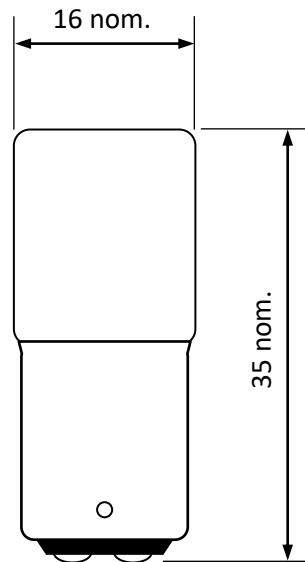

Dimensions in millimetres (Not to scale)

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
24	180	200	220	22.5	30	37.5	1,000

Notes:

- 1 **Base Type** Nickel plated BA15d base
- 2 **Marking** Lamp rating durably marked on base
- 3 **Environmental** RoHS & REACH SVHC compliant