


RoHS  
Halogen-Free


Edition	Modifier	Date	Description	ECN No.

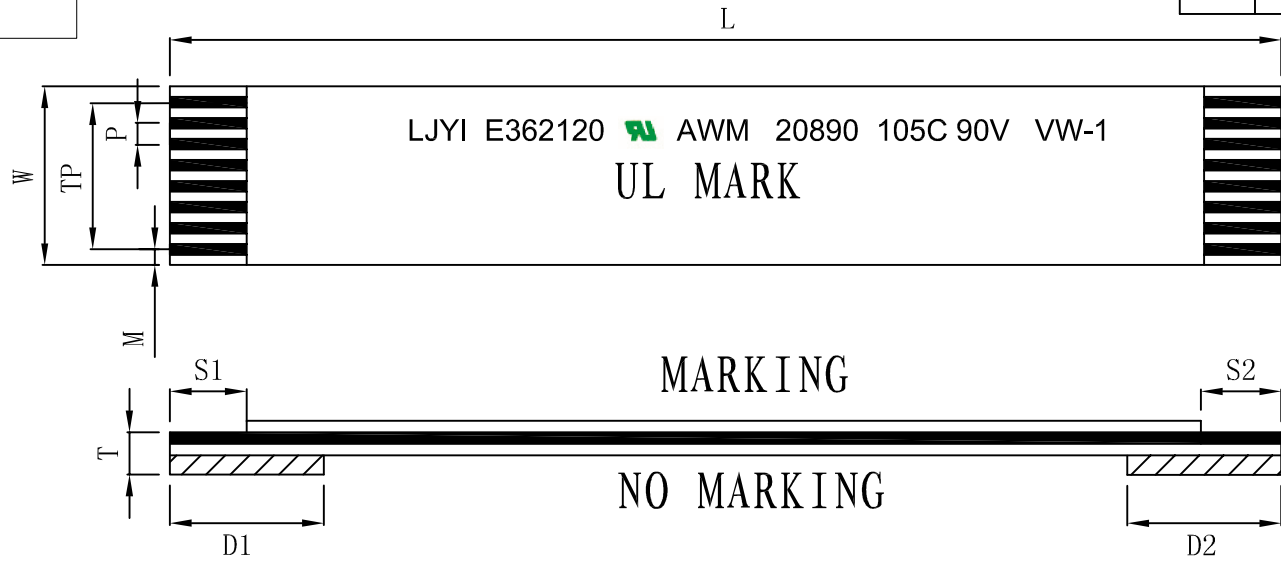

Item	Code	Spec
NO of PIN	N	6
Pitch	P	$0.5 \pm 0.05$
Total Length	L	$51 \pm 1$
Margin	M	$0.5 \pm 0.05$
Thickness	T	$0.3 \pm 0.03$
Strip Length	S1	$3.5 \pm 0.5$
	S2	$3.5 \pm 0.5$
Supporting Length	D1	$6.0 \pm 1.0$
	D2	$6.0 \pm 1.0$
Total Pitch	TP	$2.5 \pm 0.05$
Total Width	W	$3.5 \pm 0.05$
Conductors	Width	$0.3 \pm 0.03$
	Thickness	$0.035 \pm 0.005$
	Plated	Sn(1um) Min
Film	White	0.06mm
	White	0.06mm
Supporting	Blue	0.225mm
UL NO.	<b>UL20890(105 °C 90V)</b>	

Processing requirement:

NO.	Specification description	Number	Remarks
1.			

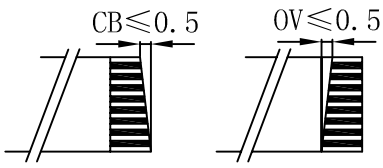

**CnC Tech, LLC**  
Industrial Cable and Connector Technology

DRAWN BY:	DATE: 2018/07/20	DESCRIPTION: 6-51-0.5-3.5/3.5-6/6-A-Tin
CHECKED BY:	SHEET 1 of 1	ITEM NO. 310-06-0051
APPROVED BY:	SCALE 1:1	REV. A/0   UNIT: mm

1

2

3

4

5

1

2

3

4

5