














SERIES: 18 ~ 36 W DESK-TOP


DESCRIPTION: LEAD ACID BATTERY CHARGER

**OUTPUT PLUG OPTIONS**

**Standard DC Plug**

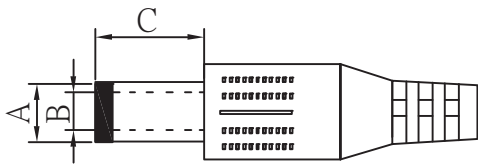


Standard PX

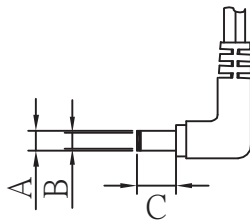

Right Angle PXR


	A	B	C	Unit
P5/P5R	5.5	2.1	12	mm
P6/P6R	5.5	2.5	12	mm
P7/P7R	3.5	1.3	10	mm
P8/P8R	3.8	1.35	10	mm
P9/P9R	3.8	1.05	10	mm

**Locking DC Plug**

 


	A	B	C	Unit
P10	5.5	2.1	12	mm
P11	5.5	2.5	12	mm

**EIAJ Plugs**

 

Standard PXX

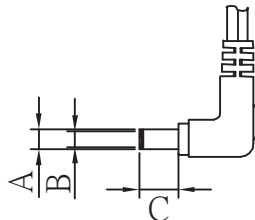

Right Angle PXXR

	EIAJ	A	B	C	Unit
P12/P12R	EIAJ-1	2.35	0.7	10	mm
P13/P13R	EIAJ-2	4.0	1.7	9.5	mm
P14/P14R	EIAJ-3	4.75	1.7	9.5	mm

Add suffix "P" for center positive: **PXXP**



Add suffix "N" for center negative: **PXXN**



\*Contact CUI for additional output plug options.