

# EG1312 SERIES SLIDE SWITCH

ANTI-VANDAL SWITCHES  
 DETECTOR SWITCHES  
 DIP SWITCHES  
 KEYLOCK SWITCHES  
 NAVIGATION SWITCHES  
 PUSHBUTTON SWITCHES  
 ROCKER SWITCHES  
 ROTARY SWITCHES  
**SLIDE SWITCHES**  
 SNAP ACTION SWITCHES  
 TACTILE SWITCHES  
 TOGGLE SWITCHES  
 CAP OPTIONS



## APPLICATIONS / MARKETS



Handheld Devices



Wearable Electronics




Internet of Things



Smart Home



Telecommunication

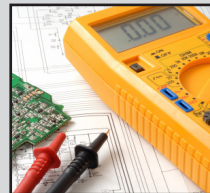

Testing Equipment

**RoHS**

## SPECIFICATIONS

**Contact Rating:** 30mA @ 15VDC  
**Electrical Life:** 5,000 cycles Min.  
**Contact Resistance:** 1Ω Max.  
**Insulation Resistance:** 1MΩ Min @ 250VDC  
**Dielectric Strength:** 100VAC  
**Operating Temperature:** -10°C to 60°C  
**Storage Temperature:** -25°C to 85°C  
**Travel:** 1.50mm from each position to the next position  
**Contact Arrangement:** SP3T  
**Actuation Force:** 150gF

## FEATURES & BENEFITS

- Surface mount PC board design
- 1.50mm travel
- Compact design
- SP3T function

## PART NUMBER CONFIGURATOR

Series



EG1312

Actuator  
Option



A - 1.00mm

Momentary  
Position



R - Right Side

*Specifications subject to change without notice 7.20.2020*



**E-SWITCH®**






www.e-switch.com

800.867.2717

1

# EG1312 SERIES SLIDE SWITCH

## BODY DIMENSIONS

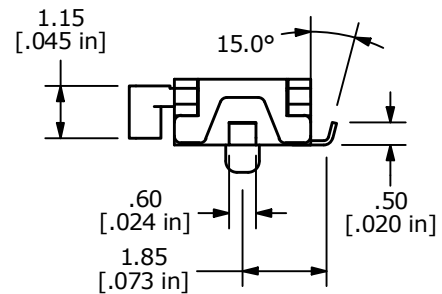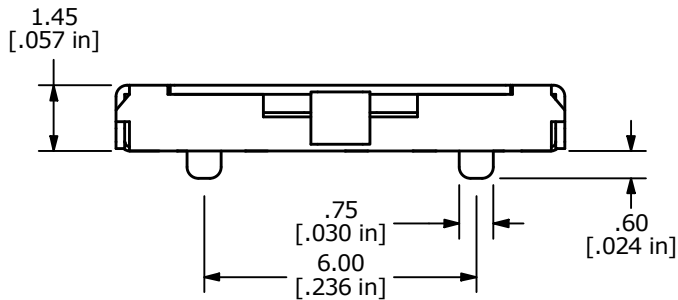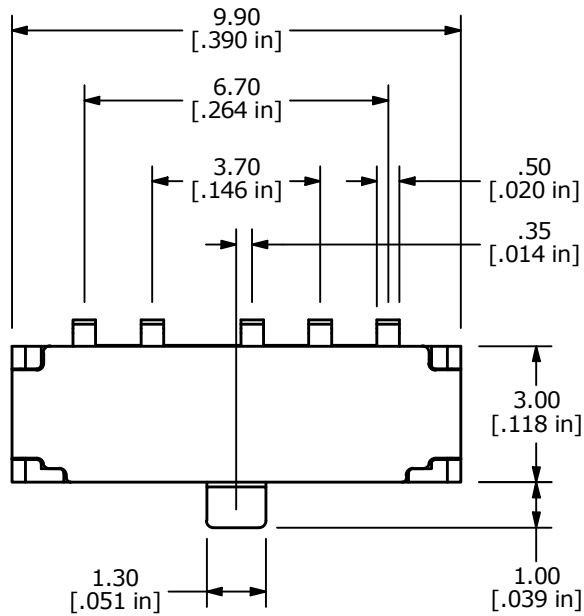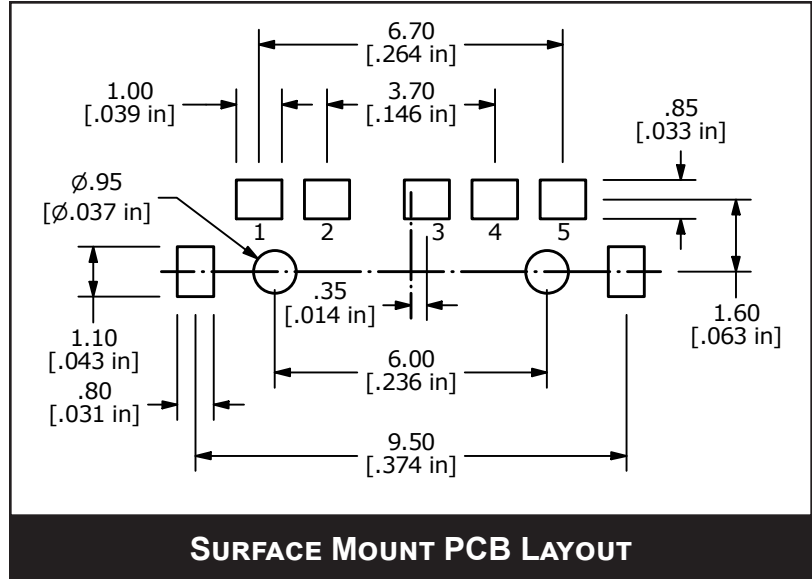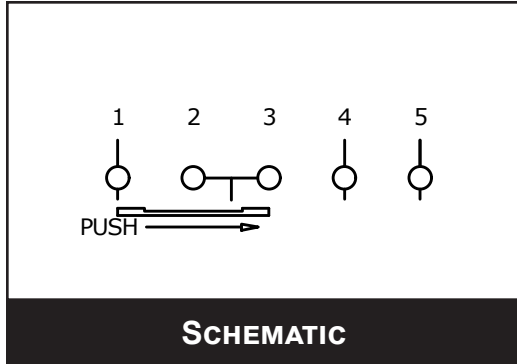

ANTI-VANDAL SWITCHES  
 DETECTOR SWITCHES  
 DIP SWITCHES  
 KEYLOCK SWITCHES  
 NAVIGATION SWITCHES  
 PUSHBUTTON SWITCHES  
 ROCKER SWITCHES  
 ROTARY SWITCHES  
 SLIDE SWITCHES  
 SNAP ACTION SWITCHES  
 TACTILE SWITCHES  
 TOGGLE SWITCHES  
 CAP OPTIONS