




LED 7 WATT PAR20 FLOODLIGHT



Perfect for Residential and Commercial Downlight Applications

- Perfect to Replace Standard Floodlights
- Designed for use in General, Track and Recessed Lighting
- Available in 2700K, 3000K, 4000K and 5000K
- UL Approved for use in Wet Locations
- 3 Year Warranty

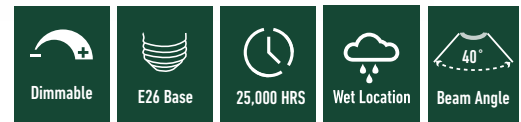

SPECIFICATIONS	41188	48137	44419	41189
ENERGY STAR® Model #	7W/LED/PAR20D/FL/27K	7W/LED/PAR20D/FL	7W/LED/PAR20D/FL	7W/LED/PAR20D/FL/50K
Type	LED PAR20	LED PAR20	LED PAR20	LED PAR20
Base	E26	E26	E26	E26
Wattage	7W	7W	7W	7W
Incandescent Equivalence	50W	50W	50W	50W
Voltage - Frequency	120V	120V	120V	120V
Color Temperature (ANSI)	Soft White 2700K	Bright White 3000K	Cool White 4000K	Daylight 5000K
Lumens	500	500	500	500
CRI	80	80	80	80
Beam Angle	40°	40°	40°	40°
Dimmable*	Yes	Yes	Yes	Yes
Rated Lifetime (hrs.)	25,000	25,000	25,000	25,000
Dia. x MOL	2.48" x 3.19"	2.48" x 3.19"	2.48" x 3.19"	2.48" x 3.19"
Warranty	3 Years	3 Years	3 Years	3 Years

*This bulb may not be compatible with all dimmers, for a complete list please visit our website.

