

PROTECTIVE FACE MASKS

SOFT & EASY TO BREATHE THROUGH
WITH NOSE BRIDGE

KEY FEATURES

- Elastic band for comfort fitment
- Adjustable nose bridge to ensure a better fit
- 3-Ply non-woven Polypropylene and non-melt blown woven
- High breathability
- Soft and comfortable
- Disposable, for single use only
- Latex free construction
- 510K approved
- Manufactured in an ISO 13485 certified facility
- Manufactured in an FDA approved facility



MASK PERFORMANCE



- HIGH FILTRATION:
 - >99.9% BFE (Organic/Bacteria Filtering blocks up to 99.9%)
 - >99.5% PFE (In-Organic/Solid Filtering blocks up to 99.5%)
- Fluid resistant
- Flame resistance
- Nelson Labs

APPLICATION

Protection for the nose and mouth from droplets both inhaled and exhaled.

COLOR


- White

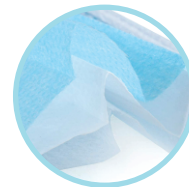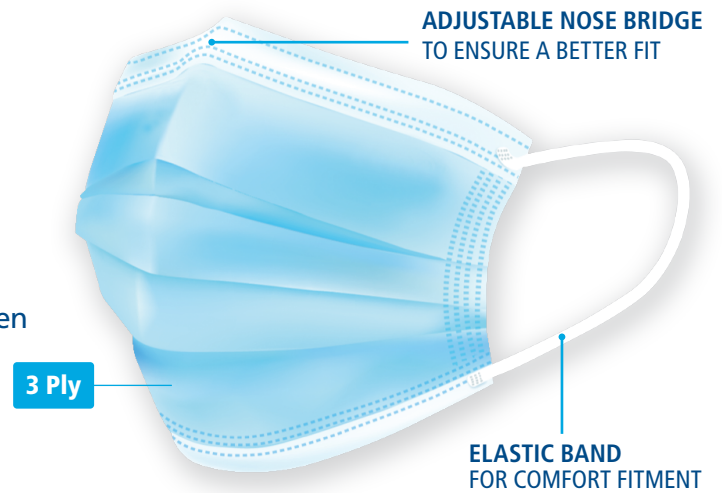

3-LAYER PROTECTION





PERFECT EDGING

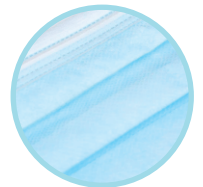

HIGH-QUALITY MATERIAL



3-LAYER PROTECTION SYSTEM

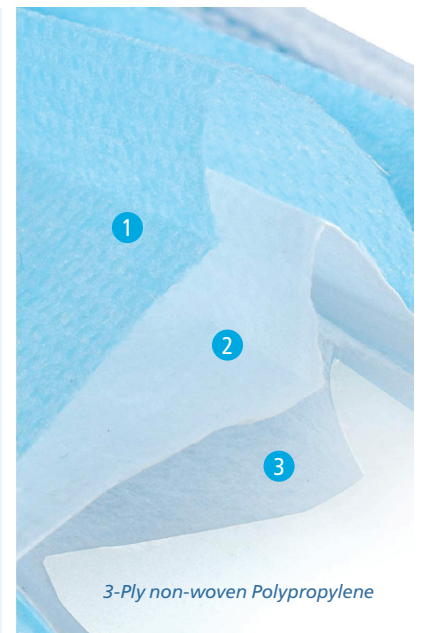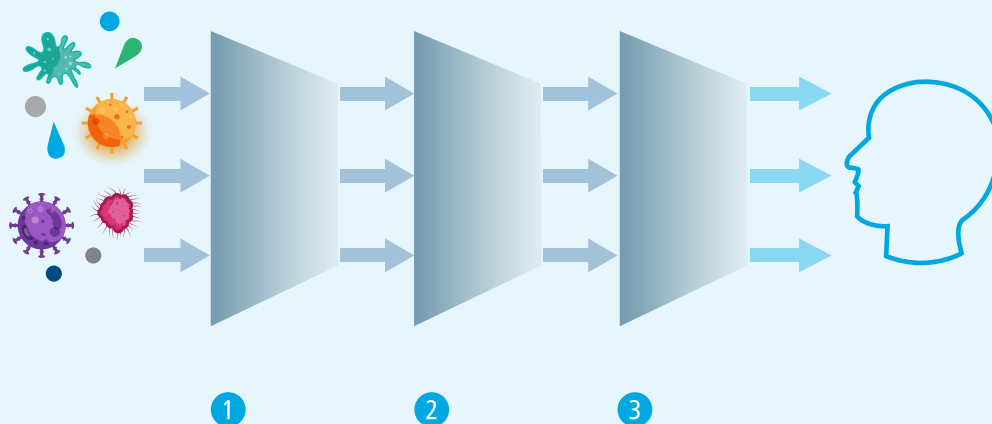

3-Ply non-woven Polypropylene

PRODUCT NAME	DISPOSABLE PROTECTIVE MASK (BLUE)
SKU Number	PTX-20190019
Type (Box/Polybag)	50 poly bag/Box
Color Box Dimension	225 x 100 x 80mm
HTS Code	6307.90.9891
Master Carton Weight (kg)	9kgs
Master Carton Dimension	520 x 450 x 340mm
Qty per Master Carton	2000
Color Box per Master Carton	40
40' container (Piece)	1,518,000 pcs
UPC	788345660461
FDA	510K approved

