


Capacitor, ceramic, 0.01 uF, +/-10% Tol, 500V, X7R, Lead Spacing=0.2"

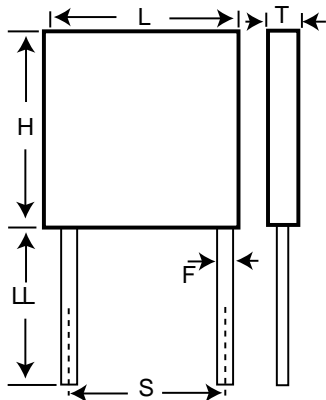

Dimensions (in)		
Symbol	Dimension	Tolerance
L	0.3	MAX
T	0.15	MAX
S	0.2	+/-0.015
LL	1.25	MIN
H	0.3	MAX

Notes:

-Lead Diameter (in) 0.020 +/- 0.002

Test Level = MIL-PRF-39014

General Information	
Supplier:	KEMET

Specifications	
Capacitance:	0.01 uF
Lead Spacing:	0.2"
Voltage:	500V
Temperature Coefficient:	X7R
Tolerance:	+/-10%
Application:	Commercial High Temp
Temperature Range:	-55/+260C
Body Type:	Radial Molded
Lead Type:	Standard Leads
Lead Form:	Straight
Termination Type:	Gold

Packaging Specifications	
Package Kind:	Bulk
Package Type:	Bag
Package Quantity:	1