

Type ANF

Automotive / Marine Limiter

Fast Acting



www.optifuse.com

(619) 593-5050

Specifications:

- **Voltage Rating:** 32 VDC
- **Amperage Rating:** 40A, 50A, 60A, 80A, 100A, 125A, 130A, 150A, 175A, 180A, 200A, 225A, 250A, 275A, 300A, 400A

- **Construction:**

Body Material: Bakelite

Terminals: Gold-plated

40A ~ 80A – Brass

100A ~ 400A – Copper Alloy



Time Characteristics	
% of Rated Current	Clearing Time
100%	Min 4h
250%	Max 300s

Recommended Mounting:

Optifuse Fuse Block BLC-09 to 200A

Optifuse Fuse Block BLC-209 to 800A

Mechanical Dimensions: Inches [mm]

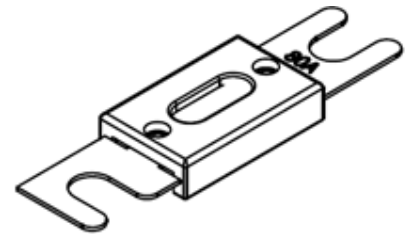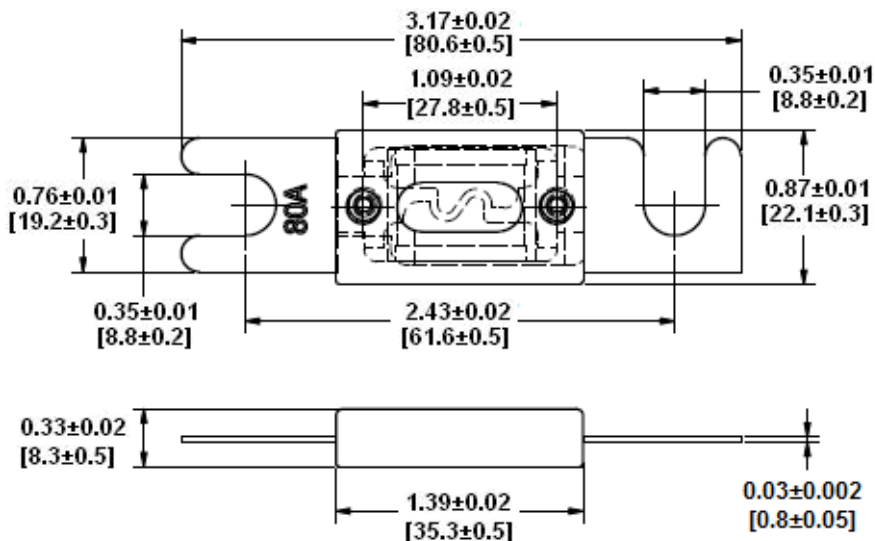

Warning:



-Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.

-Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.

Type ANF

Automotive / Marine Limiter


Fast Acting



www.optifuse.com

(619) 593-5050

Time Current Curve Graph

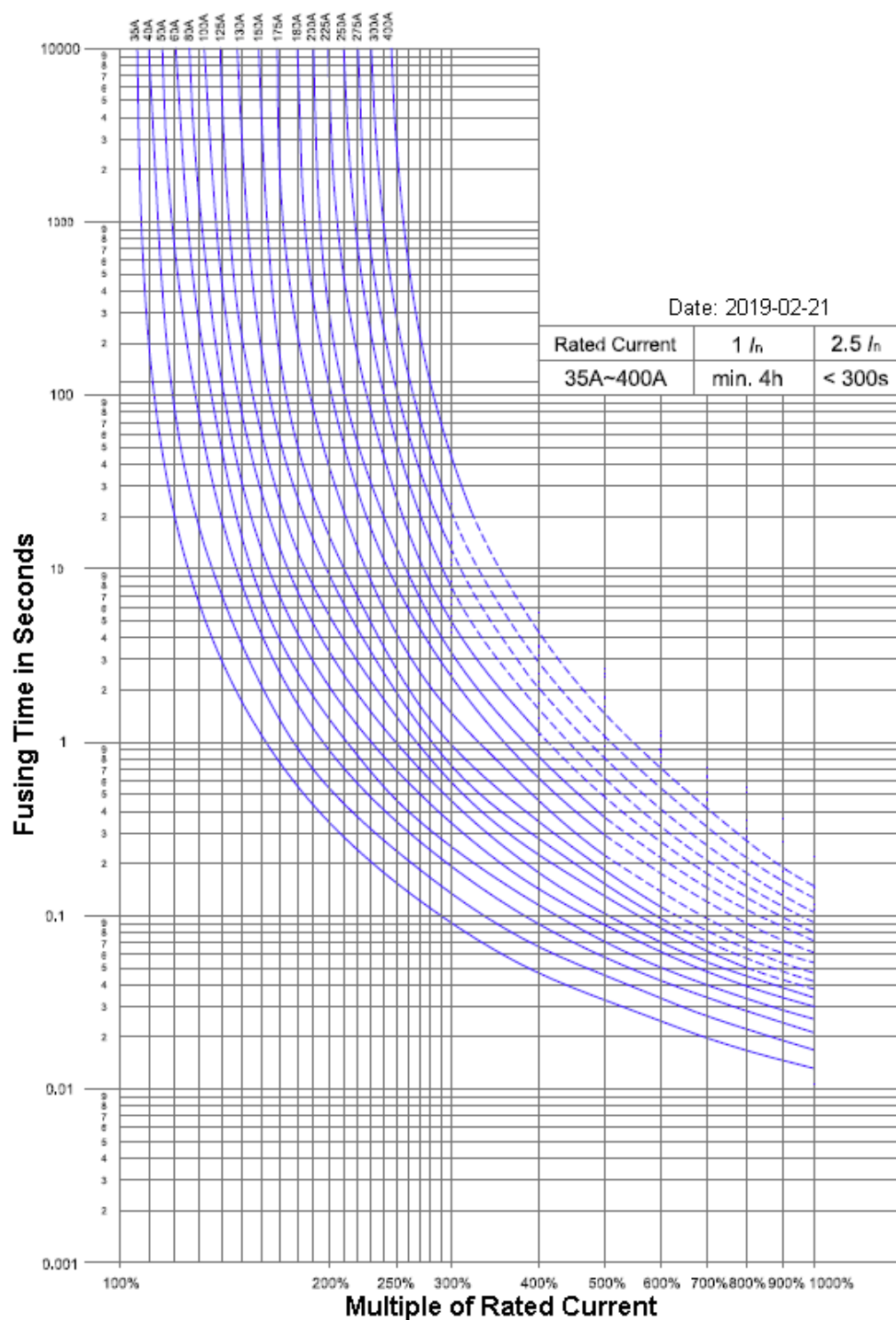

Note: All specifications subject to change without notice.

Rev D 02/2019 - Page: 2/2
Code J01-01H