


Patch panels - VS-PP-19-1HE-16-F - 1652994

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Patch panel, 19" assembly, IP20, with 16 slots for contact inserts with the Freenet system



Key commercial data

Packing unit	1 pc
GTIN	 4 017918 969967
Weight per Piece (excluding packing)	630.8 GRM
Custom tariff number	85366990
Country of origin	Switzerland

Technical data

Mechanical characteristics

Number of slots	16
Color	gray

Ambient conditions

Ambient temperature (operation)	5 °C ... 55 °C
Degree of protection	IP20

Material data

Inflammability class according to UL 94	V0
Housing material	PC-GF

Patch panels - VS-PP-19-1HE-16-F - 1652994

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27260701
eCl@ss 5.0	27260701
eCl@ss 5.1	27260701
eCl@ss 6.0	27260705
eCl@ss 7.0	27440309
eCl@ss 8.0	27440309

ETIM

ETIM 2.0	EC000764
ETIM 3.0	EC001121
ETIM 4.0	EC001121
ETIM 5.0	EC002641

UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

Accessories

Accessories

Female insert

RJ45 socket insert - VS-08-BU-RJ45-5-F/PK - 1652936



RJ45 socket insert, for the Freenet system, CAT5e, 8-pos., shielded, with cable connection (IDC fast connection), for solid wires AWG 24 ... 22

RJ45 socket insert - VS-08-BU-RJ45-6-F/PK - 1652949



RJ45 socket insert, for the Freenet system, CAT6, 8-pos., shielded, with cable connection (IDC fast connection), for litz and solid wires AWG 24 ... 22

Patch panels - VS-PP-19-1HE-16-F - 1652994

Accessories

USB female insert - VS-04-BUA-BUB-F/IP67 - 1653838



USB socket insert, 4-pos., socket USB type A on socket USB type B, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface, pluggable from both directions

USB female insert - VS-04-BUA-FK-F/IP67 - 1653854



USB socket insert, 4-pos., socket USB type A on flat-ribbon cable terminal strip, pitch 2.54, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface

USB female insert - VS-04-BUB-FK-F/IP67 - 1653867



USB socket insert, 4-pos., socket USB type B on flat-ribbon cable terminal strip, pitch 2.54, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface

Female insert - VS-06-BU-BU-F/IP67 - 1654329



FireWire socket insert, 6-pos., socket on socket, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface

Female insert - VS-06-BU-FK-F/IP67 - 1654332



FireWire socket insert, 6-pos., socket on flat-ribbon cable terminal strip, for the Freenet system in the panel mounting frame, IP20 terminal outlet, 19" patch panel and service interface, pitch: 2.54 mm

Fiber optics connector (device side)

Patch panels - VS-PP-19-1HE-16-F - 1652994

Accessories

Fiber optic coupling - VS-SCRJ-GOF-KU - 1654358



SCRJ coupling insert, duplex, for VS-PP-19-1HE-16-F patch panel and VS-TO...F...terminal outlets and VS-SI-FP-2F front plate, can be used for glass multi-mode, HCS and polymer fiber types

Rectangular connector (device side)


RJ45 socket insert - VS-08-BU-RJ45-5-F/BU - 1652952



RJ45 socket insert, for the Freenet system, CAT5e, 8-pos., shielded, socket on socket

Drawings

Dimensioned drawing

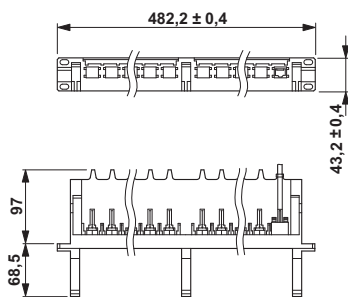

RJ45 patch panel