


Stainless steel industrial – 37.50 40 16

Enclosure base with bracket clips and threaded hole for attachment of DIN rails, 4 mounting bosses with attachment holes and sealing plugs, alternatively available without fastening holes, lid with stud bolts inside and permanently attached lid screws.

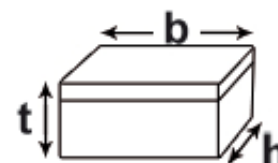

Dimensions H x W x D (mm)	500 x 400 x 161
Weight (g)	7850
Order number	37.50 40 16
Product type	IG 3785

- + Universal industrial enclosures
- + No gaps between lid/base
- + Optional individual sizes and versions from 25 off
- + Ingress protection up to IP 69K



Technical Data

Material	Stainless steel 1.25 mm or 1.5 mm; 14301/304, other material on request
Colour	
Ingress protection	IP 66 to EN 60529, high pressure cleaner-resistant version (IP69) on request
Impact resistance	
Temperature range	VMQ (silicone) seal : -40°C to +80°C other temperature ranges on request
Other versions on request	EMC

Commercial Data

Country of origin	IN
Pieces per packaging	1
Customs tariff number	85369095
Weight (g)	7850
GTIN	4250157919397

Stainless steel industrial – 37.50 40 16

ETIM Classification

ETIM-Class	EC000058
------------	----------

Accessories

Description	Order number
Mounting set	37.99 00 01
External hinges Set = 2 pcs	37.00 00 02
External mounting brackets set = 4 pcs	37.10 50 00
Mounting plate	10.01 10 49