

Type LPT-04 In-Line Fuse Indicating Holder Tiny (Micro, 2 leg) Auto Blade Fuses Waterproof



www.optifuse.com (619) 593-5050

Ratings:

Fuse Type: Tiny (Micro, 2 leg) Auto Blade – APT, ANT

Electrical Rating: see Wire Gauge table

Body: PVC

Contacts: Tin plated Brass

IP Rating: IP67

Standard Wire Gauges: #12 ~ #18 AWG UL1015

Standard Wire Colors: Red

Standard Body colors: Black

Standard Wire Length: 5 inches


Standard Wire Gauges		
Wire Gauge	Rating	Wire Color
#12	30A 32VDC	Red
#14	20A 32VDC	Red
#16	15A 32VDC	Red
#18	10A 32VDC	Red

Part number format

LPT-04B-##R

where ## = Wire gauge

Mechanical Dimensions: Inches [mm]

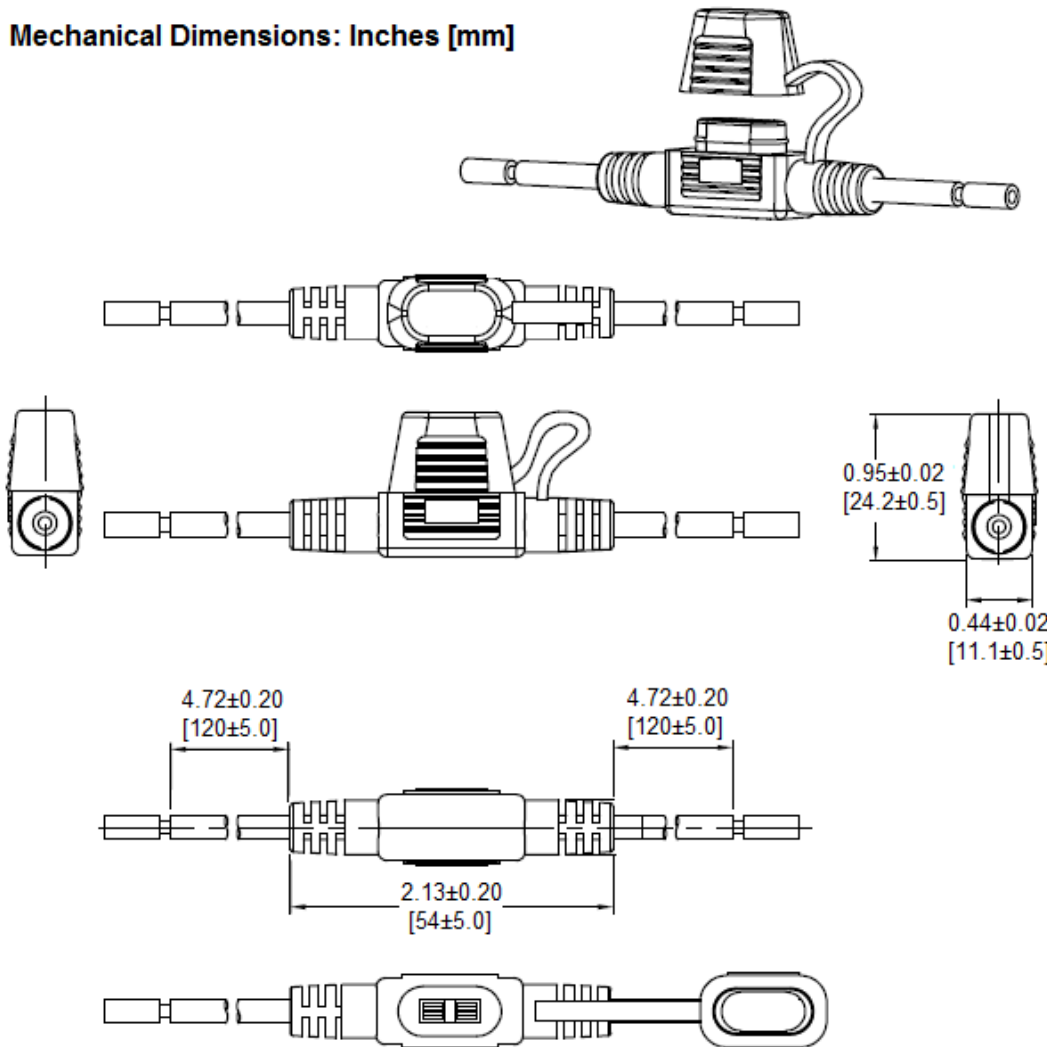

Warning:



- Operation beyond the specified maximum ratings or improper use may result in damage and possible electrical arcing and/or flame.
- Avoid contact of device with chemical solvent. Prolonged contact may damage the device performance.
- Not designed for prolonged liquid exposure or submersible applications.

Note: All specifications subject to change without notice.

Rev A 07/2018 - Page: 1/1
Code S02-02D