


**RSF
RS F10 Z**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

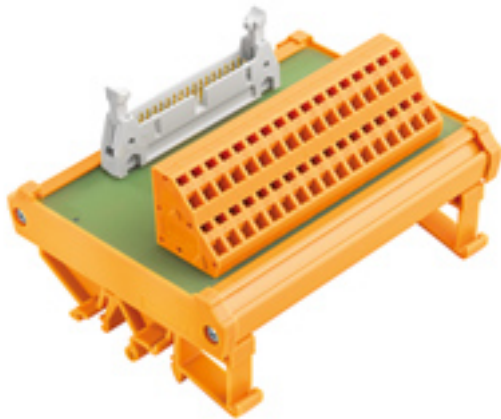

Passive interfaces for signal transmission on a flat-cable connector equipped with a tension-clamp connection in accordance with IEC 603-1 / DIN 41651. The main features include:

- Group with 10- to 64-pole connectors
- One-to-one electrical connection between controller and field connections.
- Very compact modules can be attached to conventional TS35 or TS32 mounting rails.
- Longer attachment hooks

General ordering data

Type	RS F10 Z
Order No.	8537190000
Version	Interface, RSF, Connector according IEC60603-13/DIN41651, 10-pole, Tension clamp connection
GTIN (EAN)	4032248172948
Qty.	1 pc(s).

Data sheet

**RSF
RS F10 Z**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Technical data

Dimensions and weights

Length	50 mm	Width	87 mm
Height	64 mm	Net weight	72.7 g

Temperatures

Operating temperature	0...+55°C	Storage temperature	-40...+70 °C
-----------------------	-----------	---------------------	--------------

Connection Data

Connection on control side	Connector according IEC60603-13/DIN41651	Number of poles (control side)	10-pole
Connection (field side)	LM2NZF 5.08mm	Earthing	No

Rating data

Rated voltage	60 V AC / 75 V DC	Rated current per connection	1 A
---------------	-------------------	------------------------------	-----

Insulation coordination (EN50178)

According to	DIN EN 50178	Rated insulation voltage	100 V
Surge voltage category	II	Pollution severity level	2
Pulse voltage test (1,2/50µs)	0.8 kV		

Connection field

Type of connection	Tension clamp connection	Clamping range, min.	0.13 mm ²
Clamping range, max.	2.5 mm ²	Solid, min. H05(07) V-U	0.2 mm ²
Solid, max. H05(07) V-U	2.5 mm ²	Flexible, min. H05(07) V-K	0.2 mm ²
Flexible, max. H05(07) V-K	1.5 mm ²	Flexible with sleeve, max.	1.5 mm ²
Flexible with sleeve, min.	0.25 mm ²	Sleeve with plastic collar, max.	1.5 mm ²
Min. wire cross-section, AWG [field]	AWG 24	Max. wire cross-section, AWG [field]	AWG 14
Stripping length	7.5 mm		

Classifications

ETIM 3.0	EC001419	UNSPSC	30-21-18-01
eClass 5.1	27-24-22-04	eClass 6.2	27-24-22-04
eClass 7.1	27-24-22-04		

Product information

Descriptive text accessories	Refer to the "Universal cables PAC-UNIV" section in this chapter
------------------------------	--

Approvals

Approvals




ROHS	Conform
------	---------

Data sheet

**RSF
RS F10 Z**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

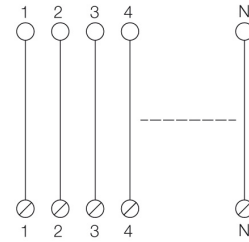

N: Number of poles