


Disconnect test terminals

SAKA 10

SAKB 10

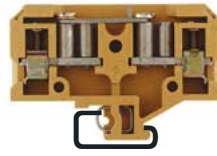

Dimensions/Approvals

Width/length/height (mm) with TS 32
 Insulation stripping length/clamping screw/screwdriver blade

12/82/55,5
 12 mm/M 4/5,5 x 1,0

10/65/52,5
 12 mm/M 4/5,5 x 1,0

Dimensions/Approvals

Width/length/height (mm) with TS 32
 Width/length/height (mm) with TS 35 x 7.5
 Insulation stripping length/clamping screw/screwdriver blade

Rated data

Rated voltage/current/cross-section
 Rated impulse voltage acc. to VDE 0110/1.89/pollution severity

500 V/47 A/10 mm²
 6 kV/3

500 V/63 A/10 mm²
 6 kV/3

Rated data

Rated voltage/current/cross-section
 Rated impulse voltage acc. to VDE 0110/1.89/pollution severity

Further technical data

Tightening torque range Nm
 Torque setting with DMS 2 electric screwdriver

1,2...2,4
 4

1,2...2,4
 4

Further technical data

Tightening torque range Nm
 Torque setting with DMS 2 electric screwdriver

Clampable conductor

Solid H07V-U mm²
 Stranded H07V-R mm²
 Flexible H07V-K mm²
 Flexible H07V-K and ferrule according to DIN 46 228/1 mm²
 Plug gauge according to IEC 60 947-1 Size

0,5...10
 1,5...10
 0,5...10
 0,5...10
 B 6

0,5...10
 1,5...10
 0,5...10
 0,5...10
 B 6

Clampable conductor

Solid H07V-U mm²
 Stranded H07V-R mm²
 Flexible H07V-K mm²
 Flexible H07V-K and ferrule according to DIN 46 228/1 mm²
 Plug gauge according to IEC 60 947-1 Size

Continuous current of terminal block for conductor size
 Continuous current rating of cross-connection 2...5-pole A
 Continuous current rating of cross-connection 6...10-pole A

(QL 2...5) 47
 (QL 6...10) 36

(QL 2...5) 47
 (QL 6...10) 36

Continuous current of terminal block for conductor size
 Continuous current rating of cross-connection 2...5-pole A
 Continuous current rating of cross-connection 6...10-pole A

UL/CSA rated data

Voltage/current/conductor size UL
 Voltage/current/conductor size CSA

600 V/35 A/18...8 AWG

600 V/45 A/18...8 AWG

UL/CSA rated data

Voltage/current/conductor size UL
 Voltage/current/conductor size CSA

Ordering data

Type
 KrG
 KrS
 KrG
 KrG
 KrS

Cat. No. Qty.
0134120000 25

Cat. No. Qty.
0134920000 40

Ordering data

Type
 Closed back wall KrG
 Open back wall KrG
 4 StB 14 KrG 60 V*
 1 StB 2 KrG
 1 StB 2.3 KrG
 2 StB 14 KrG
 2 StB 2.3 KrG
 PA
 2 StB PA

End plate (Thickness mm)

KrG
 KrS
 PA

Type Cat. No. Qty.
 AP (3,0) **0134220000** 20

Type Cat. No. Qty.
 AP (3,0) **0146720000** 20

Partition (Thickness mm)

KrG

Type Cat. No. Qty.
 TW (3,0) **0257120000** 20

Type Cat. No. Qty.
 TW (3,0) **0242920000** 20

End plate/Partition/Small partition (Thickness mm)

KrG
 KrG
 AP
 PA
 PA
 HP
 TSch 2
 TW (0,5)

Cross-connection

1-pole QL 2
 3-pole QL 3
 4-pole QL 4
 10-pole QL 10
 25-pole

0135500000 50
0135600000 50
0135700000 50
0338500000 20

0114100000 100
0114300000 50
0114500000 50
0338400000 20

QL
 QB 4
 SS M4
 VH
 BS
 VH

0348700000 50
0267100000 50
0136400000 100
0135800000 50

0103300000 100
0136400000 100
0135900000 50

Cross-connection

QL 2
 QL 3
 QL 4
 VH 12
 VH 19
 BS 25
 blank
 QS 2
 QVSK 2
 QVS 3
 QVS 4

Dummy plug

made from plastic,
 to keep the place of an
 extracted plug

Test plug/Socket

PS 4
 PS 4 **0299600000** 20

PS 4S 4 **0299600000** 20

StB Plug-test socket (without using QL)
 StB 13,5 **0135200000** 50

StB 16 **0140200000** 50

Disconnecter plug (spare)

Extraction tool

for TST 4

Switchable cross-connection link

Disconnect lock

Marking tags

DEK FW/FS/...
 DEK 5 section "Accessories"

DEK 5 section "Accessories"

DEK 5 section "Accessories"

Marking tags

DEK FW/FS/...
 DEK FW/FS/...

Mounting rails, end brackets, further marking material see section "Accessories"